


COIL: @ 25°C	
RESISTANCE	160 OHMS ± 10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	6.5 VDC
MUST RELEASE	0.9 VDC

CUSTOMER DATA SHEET

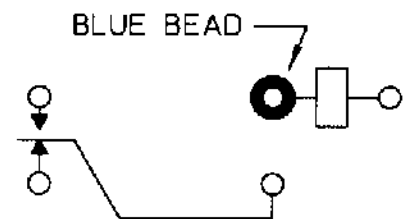

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 20 g's
SHOCK	100 g's 5 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

CONTACT RATING: 10 AMP/28 VDC
RESISTIVE 50,000 OPERATIONS

NOTES: DIELECTRIC 1000 VRMS EXCEPT
500 VRMS ACROSS OPEN CONTACTS.

DR. R.B. 11/10/97 CK. *[Signature]*

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. C. I. I. STD.
CUST. NO. _____

TYPE 'C' RELAY

CEW-1C-12B