

EKM-2050F-PO-1FN-FI06-RK
Art.-Nr.: CF1974-000 (JOR-88851)




Fuse box for lighting application EKM 2050 according to DIN 43628

explanation SKF (for installation in lighting columns and outdoor application)

- protection class II
- ingress protection IP 54
- minimum diameter 104 mm
- door opening minimum 85 x 270 mm
- l x w x h: 257 x 82 x 98 mm
- grey cover with screw
- protection cover
- 1 mounting rail TS 35 for application of installation devices
- 1 FI- protective switch 2-pin / 25mA
- 1 modular terminal block
- 1 built-in safety socket in the cover
- 1 fixing rail
- 2 pole clamping screws M 6 x 12
- cable entry: cable clamp for 1 cable to 3 cables \varnothing 19-22 mm
- output: 2 cable glands, cable \varnothing 8-14 mm

Two additional luminaire cables can be routed towards the bottom of the box.

Circuit diagram:

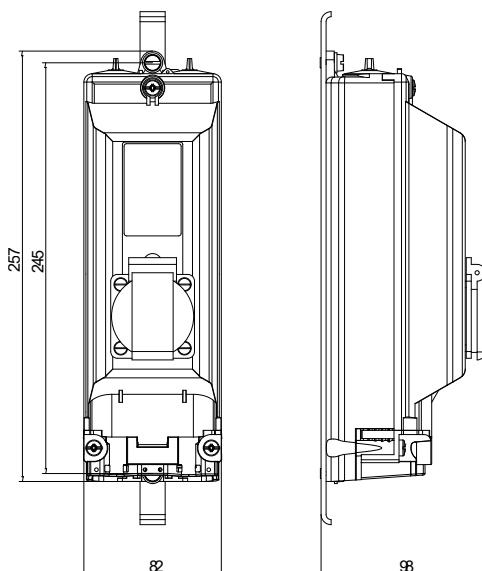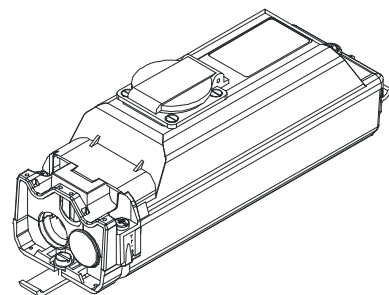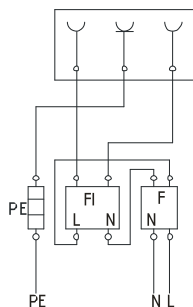

Cable entry

