

EKM-2020-1D1-0SA
Art.-Nr.: EK6500-000



Fuse box for lighting application EKM 2020
According to DIN EN 61439

For installation in lighting columns

Protection class II

Ingress protection IP 44

Minimum diameter 84 mm

Door opening minimum 70 x 240 mm

l x w x h: 232 x 69 x 69,5 mm

Transparent cover with snap hook

1 fuse bases 16 A / D01-E 14 with screw cap E 14

5 mantle terminals


Rail connection (brass rails, nickel-plated)

Fully insulated PE- and n- output terminals

cable entry: cable clamp for 1 cable to 3 cables 5 x 2,5 – 16 mm²

output: 2 insertion sealing grommets, 2 x 5 x 2,5 mm²


Two additional luminaire cables can be routed towards the bottom of the box.

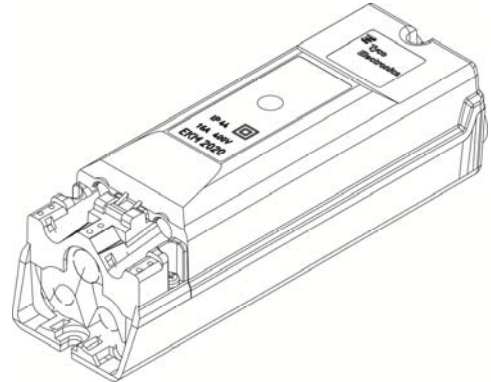

Place for 1x surge arrester TYP 2+3 (MLPX1-230L)

Single phase, for parallel or serial connection

Order description: **COBOX-SLSA10-W-O-01**

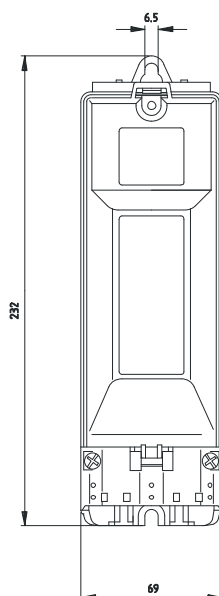

Cable entry

