

EKM-2050-2D1-5S6/U

Art.Nr.: EK6501-000



Fuse Box for Lighting Application EKM 2050

According to DIN EN 61439

SK for installation in lighting columns

Protection class II

Ingress protection IP 54

Minimum pole diameter of 89 mm

Door opening minimum 85 x 270 mm

l x w x h: 257 x 82 x 63

Transparent cover

5 sliding terminals with hexagonal screws

Prewired with bars (N, L1, (L3), L2, PE(N))

2 fuses D01 (E14) up to 16 A

2 screw caps

All metal parts corrosion protected (Ni-plated brass or stainless steel)

For up to 3 earth cables 4x4 mm² - 16 mm² 1 or 2 earth cables 4x25 mm²

With easy adaptable cable sealing for 1-3 earth cables Ø 19 – 24 mm



For 2 luminaire cables 3 x 1,5 mm² - 5 x 2,5 mm²

2 sealing grommets for luminaire cables Ø 8 – 14 mm

Two additional luminaire cables can be routed towards the bottom of the box

Standard Packing size: 1

circuit diagram:

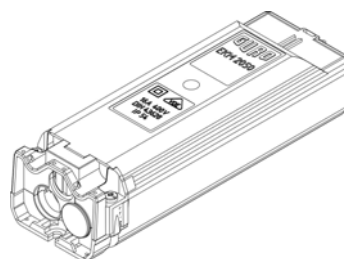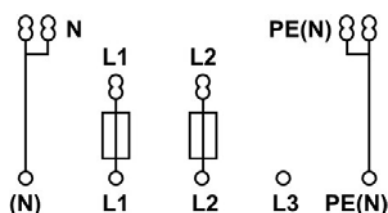

cable entry

