

EKM-2035-1D2-4S6
Art.-Nr.: EK6529-000



Fuse box for lighting application EKM 2035
According to DIN EN 61439

for installation in lighting columns

Protection class II

Ingress protection IP 44

Minimum pole diameter 110 mm

Door opening minimum 90 x 300 mm

l x w x h: 290 x 93,5 x 89 mm

Transparent cover with screw

Protection cover




1 fuse base 25 A / DII-E 27

4 sliding terminals with Allen key screws

sliding terminal connection (brass rails, nickel-plated)

cable entry: cable clamp for 1 cables to 2 cables 4 x 4 – 50 mm²
for 3 cables 4 x 4 – 35 mm²

Load side: 2 sealing grommets for 1 cable 4-11 mm ea. or 4 wires 1,5 to 3 mm ea.

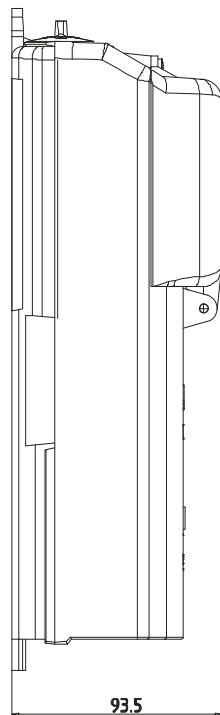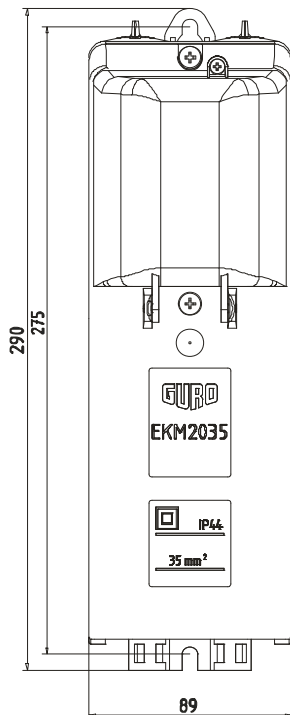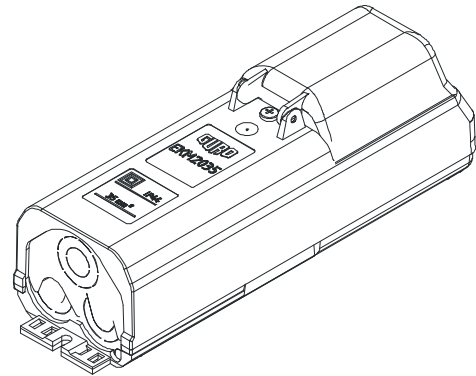

Cable entry

