

REV. B
DCO 300860


TOLERANCES $\pm .010$ " - UNLESS OTHERWISE SPECIFIED

| | |
|---|----------------------------|
| COIL: @ 25°C | |
| RESISTANCE | 320 OHMS $\pm 10\%$ |
| NOMINAL VOLTAGE | 28 VDC |
| MUST OPERATE | 13.5 VDC MAX. |
| COIL TRANSIENT SUPPRESSION: 42 VDC MAX. | |
| MUST RELEASE | 5.5 VDC MAX., 2.3 VDC MIN. |

| | |
|--------------|---------------------------|
| ENVIRONMENT: | |
| VIBRATION | 10 Hz TO 3000 Hz @ 30 g's |
| SHOCK | 200 g's 6 MS. DURATION |
| TEMPERATURE | -70 °C TO +125 °C |

NOTES: OPERATE, RELEASE 10 MS MAX.
CONTACT BOUNCE 1 MS MAX.
CONTACT BREAK BOUNCE 0.1 MS MAX.

CUSTOMER DATA SHEET

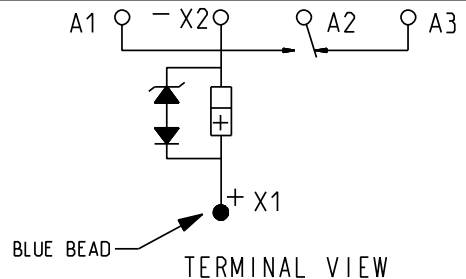

CONTACT RATING: 25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
50,000 OPERATIONS

DR. B.D. 21MAY2008 CK. J.M.B. 5/21/08

Tyco Electronics ©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. QPL
CUST. NO. M6106/19-017 REV. ----

TE NUMBER
2-1617748-3

CII PART NUMBER
FCA-125-17