


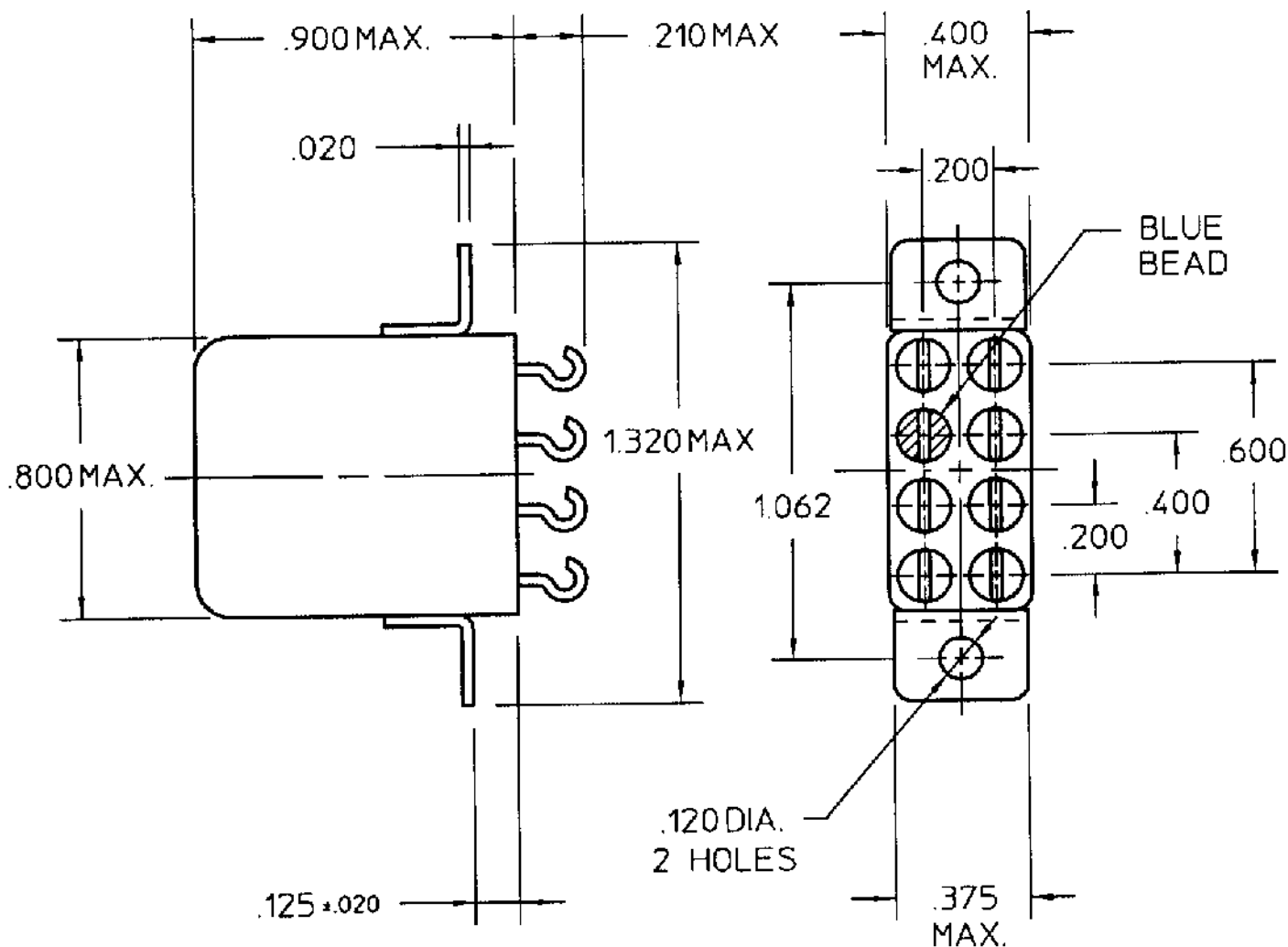


COIL: @ 25° C  
 RESISTANCE 425 OHMS ± 10%  
 NOMINAL VOLTAGE 22.0 VDC  
 MUST OPERATE 9.8 VDC  
 MUST RELEASE 1.07 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's  
 SHOCK 100 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE TIME 5 MS MAX.  
 CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

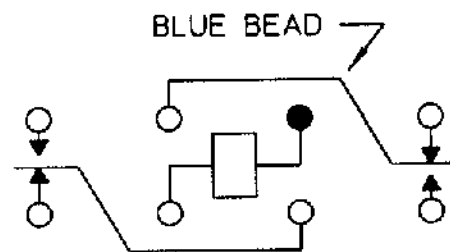

CONTACT RATING: LOW LEVEL TO 3 AMPS  
 RESISTIVE 28 VDC 100,000 OPERATIONS

DR. R.B. 7/17/96

CK. 7/17/96

COMMUNICATIONS  
 INSTRUMENTS, INC.

CUST. C. I. I. STD.  
 CUST. NO.

TYPE "FW" RELAY

FW1120F00