


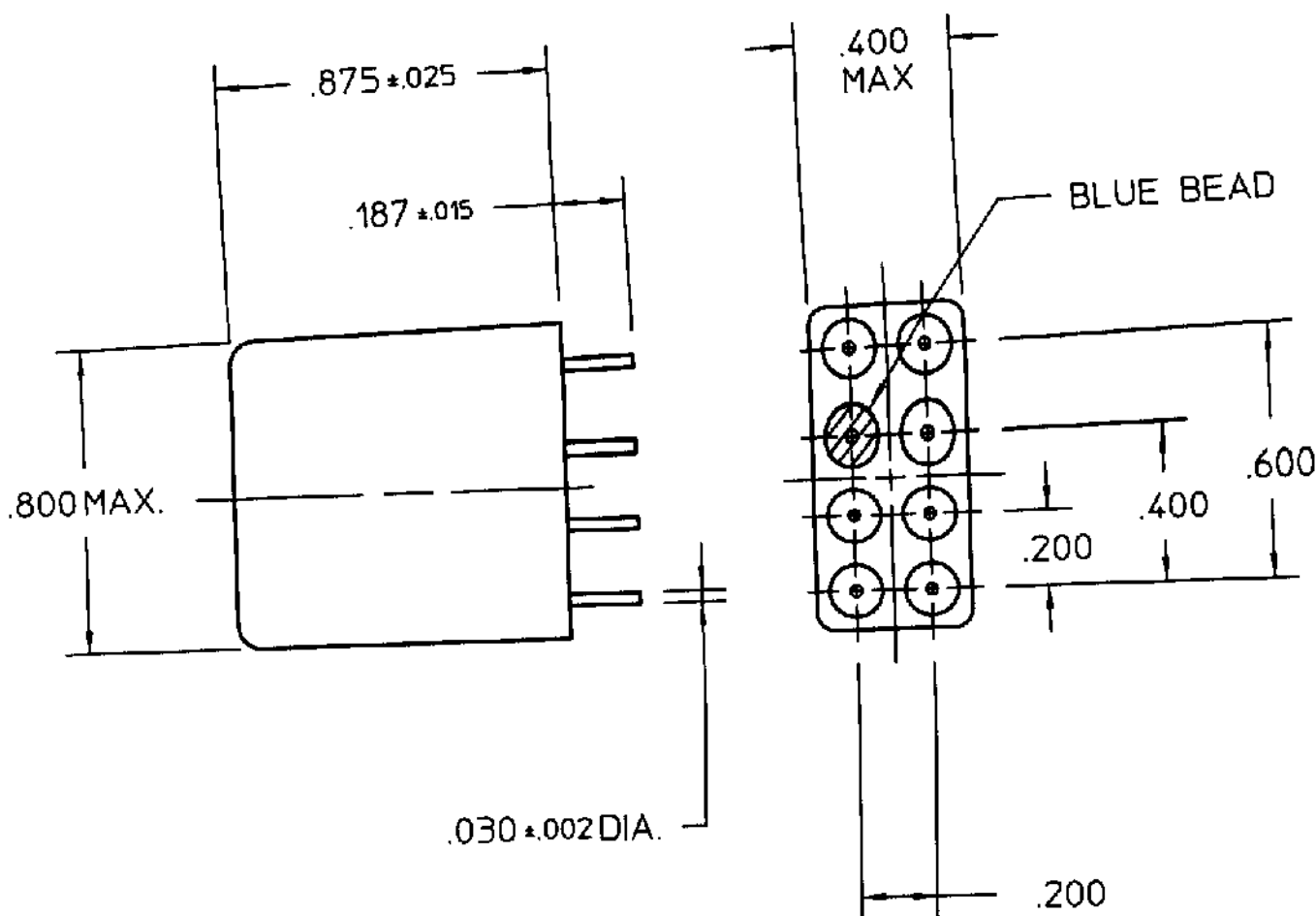

REV. 0
DCO 16232


COIL: @ 25°C
 RESISTANCE 194 OHMS +10% -15%
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 6.4 VDC
 MUST RELEASE 4.3 VDC MAX., .5 MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 ± 1 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 6 MS. MAX.
CONTACT BOUNCE 1 MS. MAX.

CUSTOMER DATA SHEET

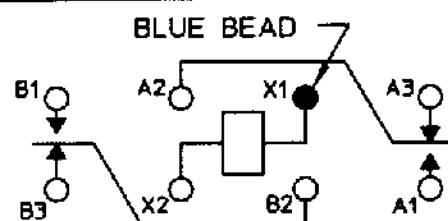

TERMINAL VIEW

CONTACT RATING: 2 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS MINIMUM

DR. P8B 5-4-00

CK. 5/5/00 JAB

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. OPL
 CUST. NO. M5757/10-060 REV.

"FW" RELAY

FW1201D02