

REV. 0
DCO 16554


COIL: @ 25°C	
RESISTANCE	44 OHMS ±10%
NOMINAL VOLTAGE	6.0 VDC
MUST OPERATE	3.0 VDC
MUST RELEASE	2.1 VDC MAX., .21 MIN.

ENVIRONMENT:

VIBRATION	10	CPS TO	2000	CPS @	20	g's
SHOCK	100	g's	6 ± 1	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES: OPERATE & RELEASE 6 MS MAX.
CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

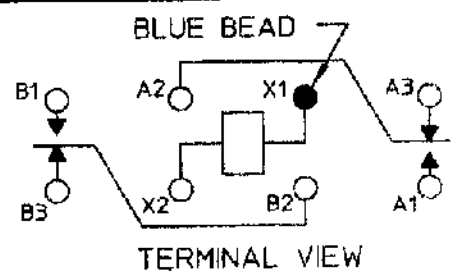

CONTACT RATING:	
	2 AMPS 28 VDC RESISTIVE
	100,000 OPERATIONS MINIMUM

DR. PBB 10/13/00 | CK. TLG 10-16-00



CUST. OPL	"FW" RELAY
CUST. NO. M5757/10-059 REV.	

FW1201S07