


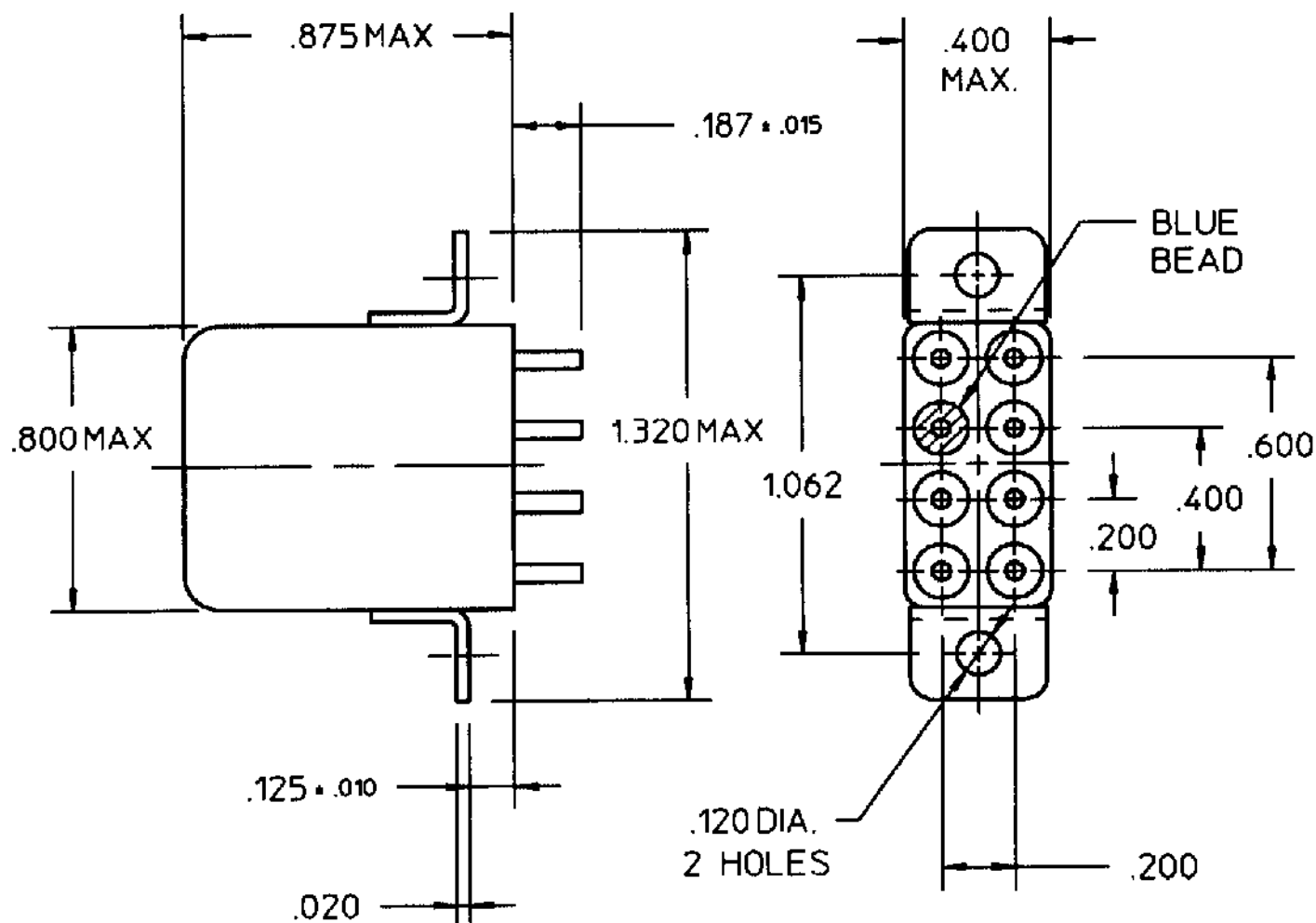

COIL:

RESISTANCE 3150 OHMS ± 10%

NOMINAL VOLTAGE 56.0 VDC

MUST OPERATE 30.0 VDC

MUST RELEASE 3.27 VDC

ENVIRONMENT:


VIBRATION 10 CPS TO 2000 CPS @ 20 g's

SHOCK 100 g's 6 ± 1 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

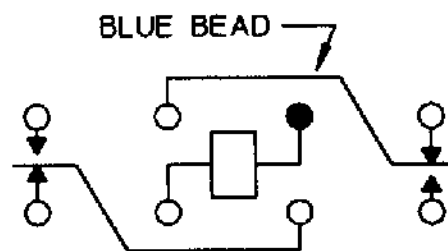

CONTACT RATING: 3 AMPS 28 VDC

RESISTIVE 100,000 OPERATIONS

DR. R.B. 11/15/91 CK. 11/15/91

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I. STD.

CUST. NO. _____

TYPE **'FW'** RELAY

FW1220M00