
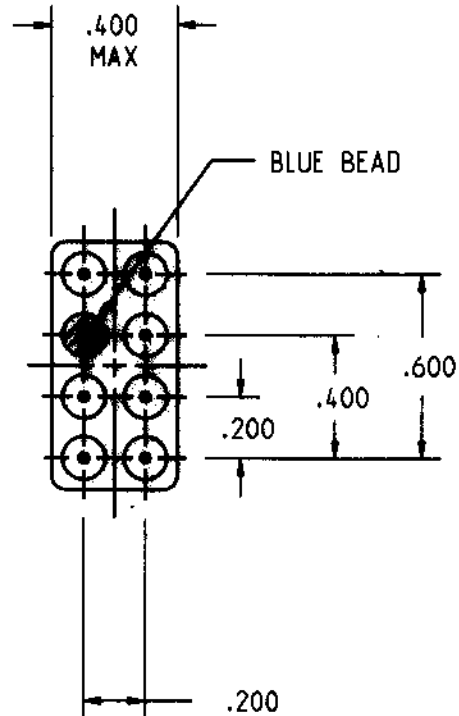


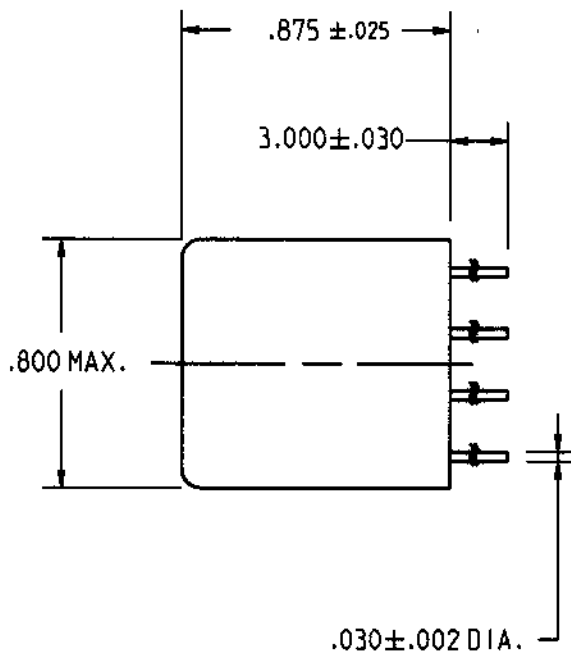


REV. 0
DCD 17705

COIL: @ 25°C
RESISTANCE 540 - 770 OHMS
NOMINAL VOLTAGE 26.5 VDC
MUST OPERATE 13.0 VDC
MUST RELEASE 10.1 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:
VIBRATION 10 Hz TO 2000 Hz @ 15 g's
SHOCK 100 g's 6±1 MS. DURATION
TEMPERATURE -65 °C TO +125 °C
NOTES: OPERATE & RELEASE 6 MS MAX.
CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

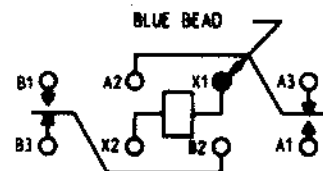

TERMINAL VIEW

CONTACT RATING: 2A 28 VDC RESISTIVE 100,000
OPERATIONS MINIMUM

DR. ASB 13JAN04

CK 1/13/04

CII Technologies
advanced control electronic solutions

CUST. QPL
CUST. NO. M5757/10-053 REV.

"FW" RELAY

FW 1301G02