

REV. 1 11/20/97

COIL:


RESISTANCE 1600 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 18.0 VDC
 MUST RELEASE _____

ENVIRONMENT:

VIBRATION 10 CPS TO 500 CPS @ 10 g's
 SHOCK 30 g's 6 MS. DURATION
 TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 6.0 MS MAX

CUSTOMER DATA SHEET

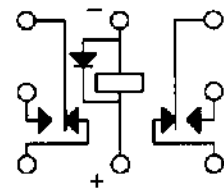

CONTACT RATING: LOW LEVEL TO 1 AMP
26 VDC RESISTIVE 100,000 OPERATIONS MIN.

DR. R.B. 11/24/92 *CK Eddy* 11/24/97

COMMUNICATIONS INSTRUMENTS, INC.

CUST. C. I. I. STD.
 CUST. NO. _____

TYPE "HCD" RELAY

HCD3-26B