

REV. 1 11/20/97

COIL:


RESISTANCE 64 OHMS
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE 3.8 VDC
 MUST RELEASE _____

ENVIRONMENT:

VIBRATION 10 CPS TO 500 CPS @ 10 g's
 SHOCK 30 g's 6 MS. DURATION
 TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 6.0 MS MAX

CUSTOMER DATA SHEET

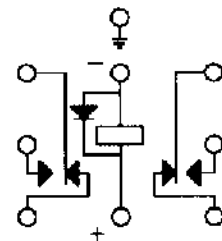

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS MIN.

DR. R.B. 10/7/92

(Signature) 11/20/97

**COMMUNICATIONS
 INSTRUMENTS, INC.**

CUST. C.I.I. STD.
 CUST. NO. _____

TYPE "HCDF" RELAY

HCDF-5B