


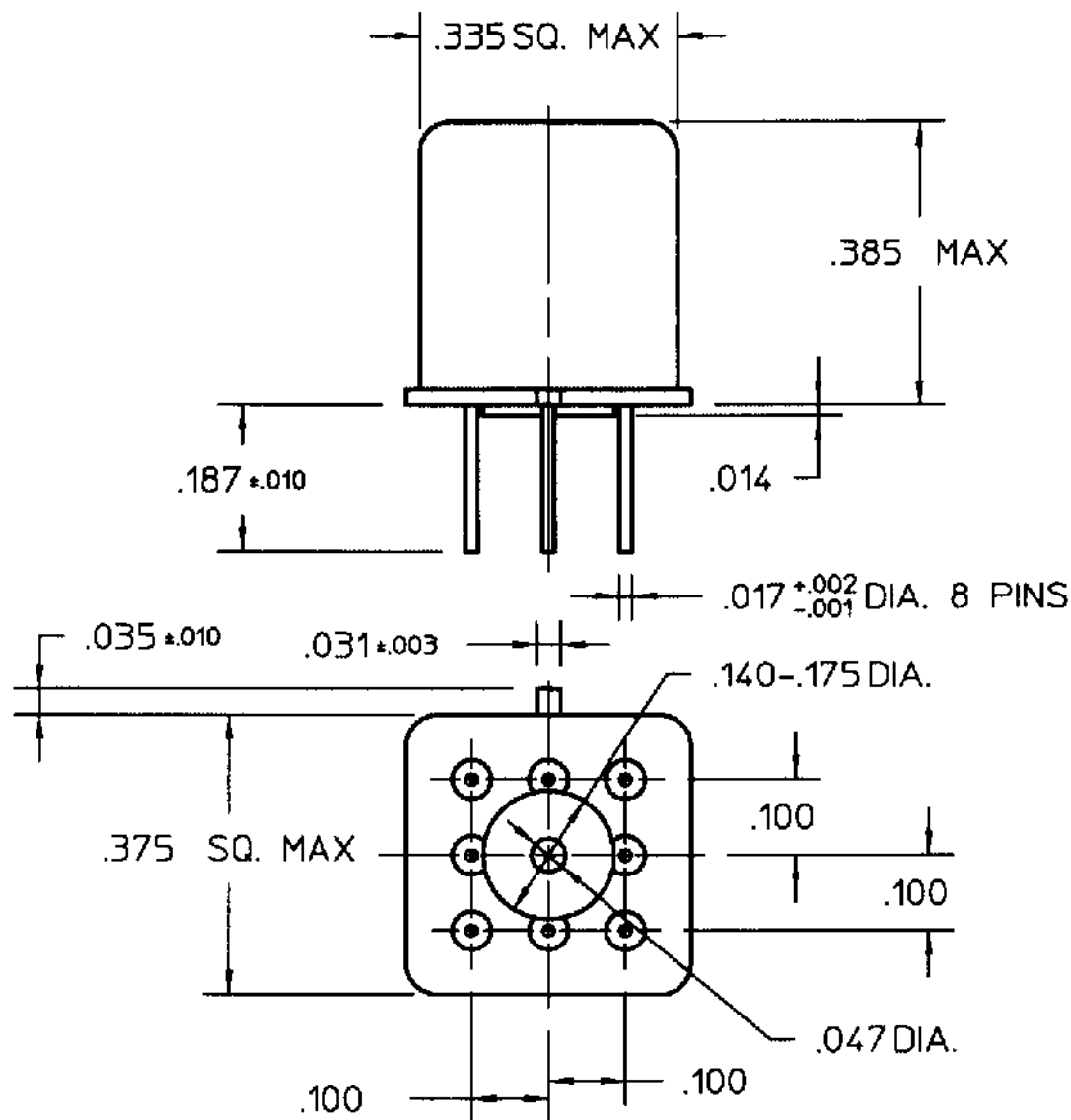

COIL:


RESISTANCE 100 OHMS ± 10%
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE 3.5 VDC
 MUST RELEASE _____

ENVIRONMENT:

VIBRATION 10 CPS TO 500 CPS @ 10 g's
 SHOCK 30 g's 6 MS. DURATION
 TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 6.0 MS MAX
RELEASE TIME 3.0 MS MAX

CUSTOMER DATA SHEET

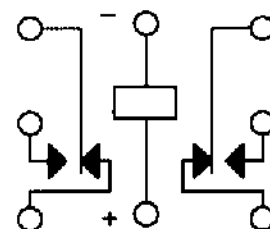

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. R.B. 9/10/98 CK JERRY 9/10/98



COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C.I.I. STD.
 CUST. NO. _____

TYPE HCS RELAY

HCS3-5C