


REV. 0
DCO 144105

| | |
|-----------------|----------------|
| COIL: @ 25°C | |
| RESISTANCE | 1250 OHMS ±10% |
| NOMINAL VOLTAGE | 26.5 VDC |
| MUST OPERATE | 14.0 VDC |
| MUST RELEASE | 1.5 VDC |

| | |
|--------------|---------------------------|
| ENVIRONMENT: | |
| VIBRATION | 10 Hz TO 2000 Hz @ 20 g's |
| SHOCK | 100 g's 6 MS. DURATION |
| TEMPERATURE | -65 °C TO +125 °C |

NOTES: _____

CUSTOMER DATA SHEET

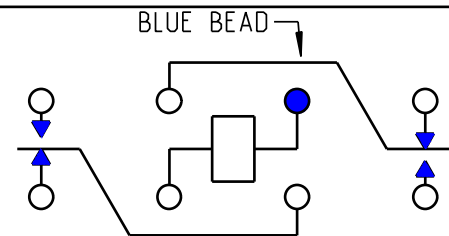

TERMINAL VIEW

| | |
|-----------------|---------------------------------|
| CONTACT RATING: | LOW LEVEL TO |
| | 2 AMPS 28 VDC RESISTIVE 100,000 |
| | OPERATIONS |

DR. ASB 17OCT05 | CK. JMB 10/7/05

CII Technologies
advanced control electronic solutions

CUST. CII STD
 CUST. NO. _____ REV. _____

"HFW" RELAY

HF1103D00