


REV. 0  
DCO 17465

COIL: @ 25°C	
RESISTANCE	320 OHMS ±10%
NOMINAL VOLTAGE	12-15 VDC
MUST OPERATE	6.8 VDC
MUST RELEASE	0.68 VDC

ENVIRONMENT:	
VIBRATION	10 Hz TO 2000 Hz @ 20 g's
SHOCK	100 g's 6 ± 1 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE 4 MS MAX. RELEASE 4 MS MAX. CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

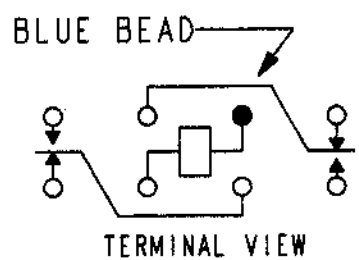

CONTACT RATING: LOW LEVEL TO  
2 AMPS 30 VDC RESISTIVE  
100,000 OPERATIONS

DR. B.D. 1/7/02 CK 116-1-7-02

**CII Technologies**  
advanced control electronic solutions

CUST. C.I.I.  
CUST. NO. STD. REV.

"HFV" RELAY

HFV1130B00