


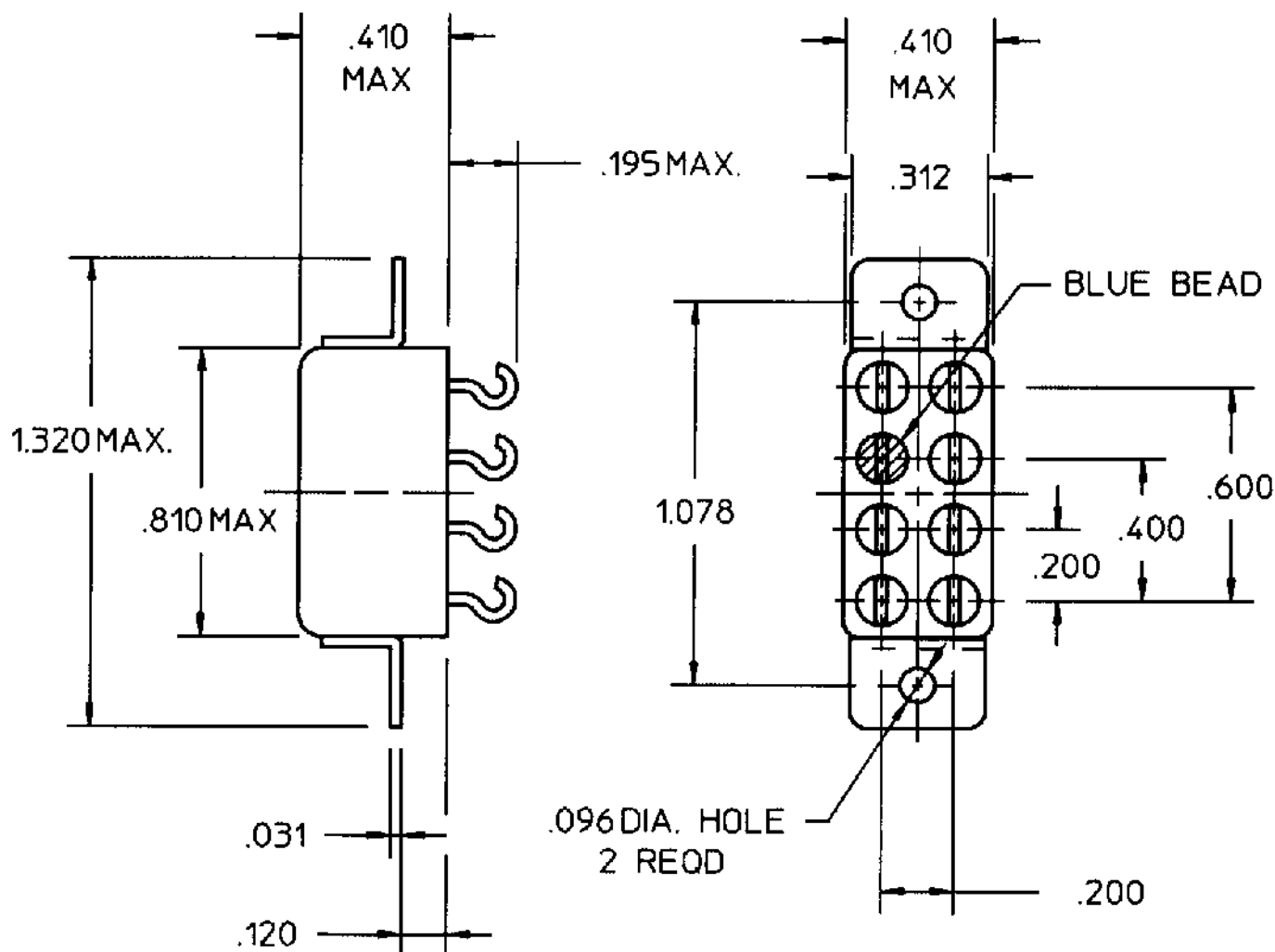

REV. 1 7/17/92

COIL:


RESISTANCE 700 OHMS $\pm$ 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 13.5 VDC
 MUST RELEASE 1.5 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

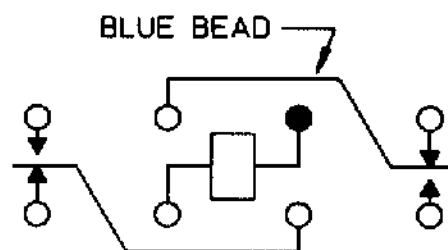

CONTACT RATING: 2A 30 VDC
RESISTIVE .75A 30 VDC INDUCTIVE
100,000 OPERATIONS

DR. R.B. 12/4/91 CK. 7/17/94

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. Hi-G
 CUST. NO. 2K-1C-126

TYPE "HFW" RELAY

HFW1140S01