

COIL: @ 25°C


RESISTANCE 40 OHMS ± 10%  
 NOMINAL VOLTAGE 6.0 Vdc  
 MUST OPERATE 3.2 Vdc  
 MUST RELEASE .35 Vdc

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS AT 100 g's  
 SHOCK 65 g's 11 ± 1 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: RELAY IS RATED FOR GROUNDED CASE APPLICATION

CUSTOMER DATA SHEET

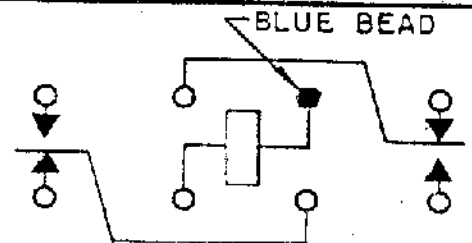

CONTACT RATING: 2 A @ 28 Vdc,  
.3 A @ 115 Vac, .75 A @ 28 Vdc  
(.200 HENRY), LOW LEVEL  
10-50 μA @ 10-50 mVdc

DR. 01-12-82

CK. JAL



**Communications  
Instruments, Inc.**

CUST. QPL  
 CUST. NO. M39016/6-123L

TYPE HFV RELAY

HFV 1201 F01