


COIL: @ 25° C
 RESISTANCE 160 OHMS ± 10%
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 6.0 VDC
 MUST RELEASE .7 VDC

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS AT 20 g's
 SHOCK 100 g's 6 ± 1 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

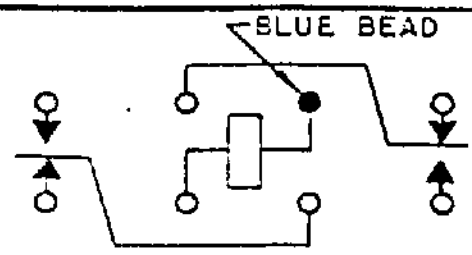

CONTACT RATING: LOW LEVEL TO
2 A @ 28 VDC

DR. 1-23-84 CK. OSW



CUST. QPL
 CUST. NO. 39016/6-216L

TYPE HFW RELAY

HFW 1201G02