


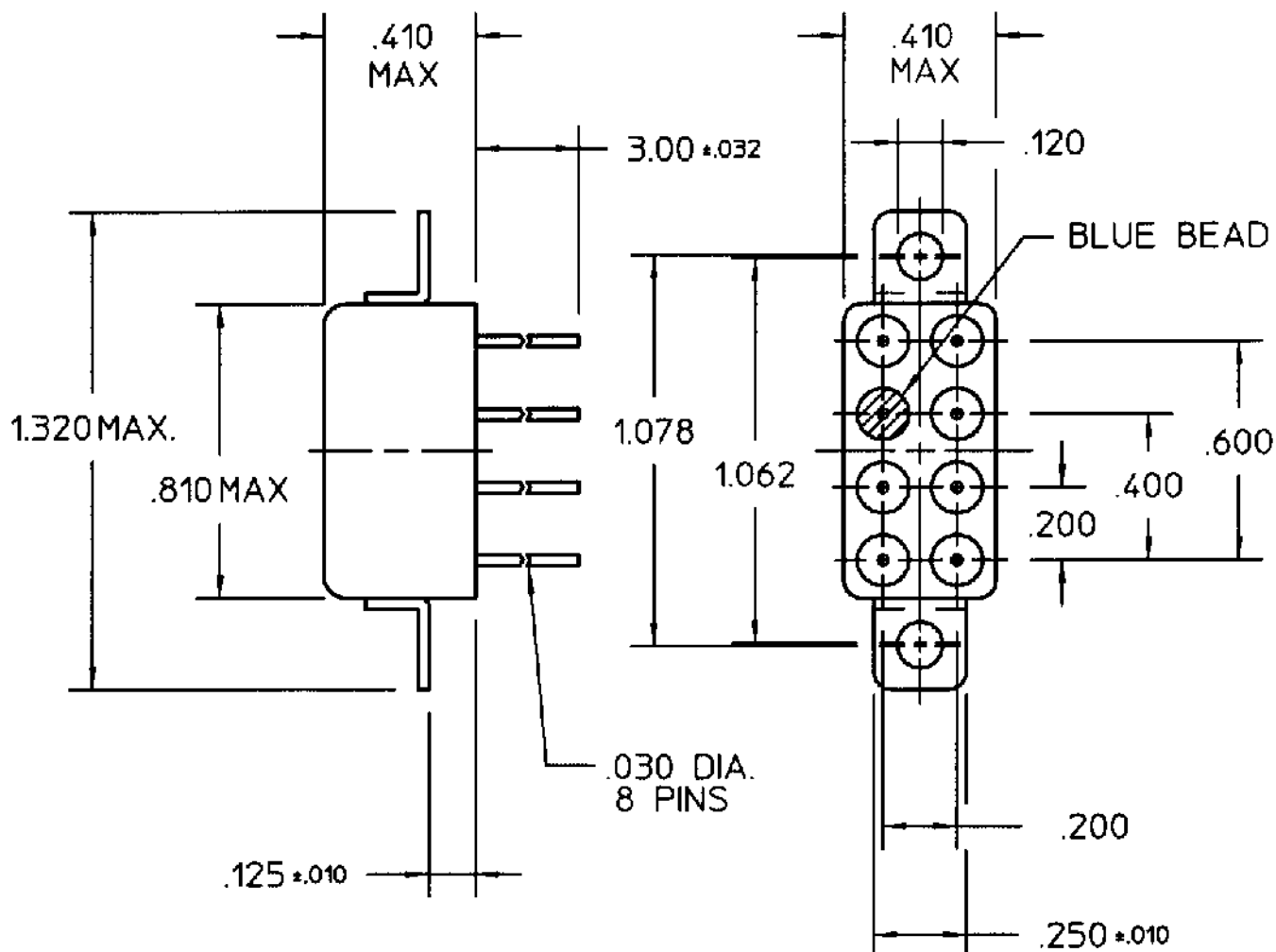

REV. 0
DCO 16298


COIL: @ 25°C
RESISTANCE _____ 700 OHMS ± 10%
NOMINAL VOLTAGE _____ 26.5 VDC
MUST OPERATE _____ 13.5 VDC
MUST RELEASE _____ 1.5 VDC

ENVIRONMENT:

VIBRATION _____ 10 CPS TO _____ 2000 CPS @ _____ 20 g's
SHOCK _____ 50 g's _____ 11 ± 1 MS. DURATION
TEMPERATURE _____ -65 °C TO _____ +125 °C

NOTES: OPERATE & RELEASE 4 MS MAX.
CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

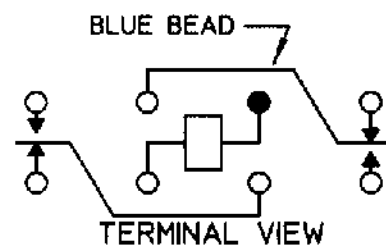

CONTACT RATING: LOW LEVEL TO 2A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 6/6/00

CK. TLG 6-6-00



COMMUNICATIONS
INSTRUMENTS, INC.

CUST. _____ C. I. I. STD.

CUST. NO. _____ REV. _____

"HFW" RELAY

HFW1330K00