


REV. 0

DCO 16056

COIL: @ 25°C	
RESISTANCE	160 OHMS ±10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	6.4 VDC
MUST RELEASE	0.7 VDC

CUSTOMER DATA SHEET

 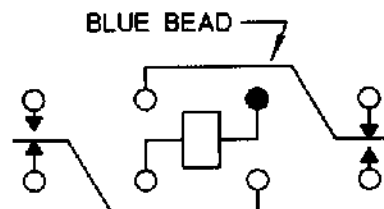


TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
5 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS MIN.

DR. B.D. 1/27/00

CK. GAW 1/27/00



ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C
 NOTES: OPERATE AND RELEASE TIMING 4.0 MS MAX.
CONTACT BOUNCE 2.0 MS MAX.

CUST. C. I. I. STD.
 CUST. NO. _____ REV. _____

HFW5A RELAY

HFW5A1130G00