


REV. 1 11/20/97

COIL: @ 25°C
 RESISTANCE 50 OHMS ± 10%
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE 3.6 VDC
 MUST RELEASE _____

ENVIRONMENT:
 VIBRATION 10 CPS TO 500 CPS @ 10 g's
 SHOCK 30 g's 6 MS. DURATION
 TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX.
RELEASE TIME 3.0 MS MAX.

CUSTOMER DATA SHEET

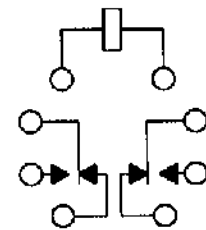

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 10/29/97 *(Signature)* 11/21/97

COMMUNICATIONS INSTRUMENTS, INC.

CUST. C. I. I. STD.
 CUST. NO. _____

TYPE "HM" RELAY

HM-5B