

REV. 2 11/21/97

COIL:

RESISTANCE 98 OHMS \pm 10%

NOMINAL VOLTAGE 6.0 VDC

MUST OPERATE 4.2 VDC

MUST RELEASE _____

ENVIRONMENT:

VIBRATION 10 CPS TO 500 CPS @ 10 g's


SHOCK 30 g's 6 MS. DURATION

TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX.

RELEASE TIME 3.0 MS MAX.

CUSTOMER DATA SHEET

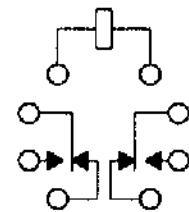

CONTACT RATING: LOW LEVEL TO 1A

28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 3/11/91 *CK* 11/21/97

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I. STD.

CUST. NO. _____

TYPE "HM" RELAY

HM-6A