

REV 2 11/21/97

COIL:


RESISTANCE 1560 OHMS \pm 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 17.0 VDC
 MUST RELEASE _____

ENVIRONMENT:

VIBRATION 10 CPS TO 500 CPS @ 10 g's
 SHOCK 30 g's 6 MS. DURATION
 TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX.
RELEASE TIME 6.0 MS MAX.

CUSTOMER DATA SHEET

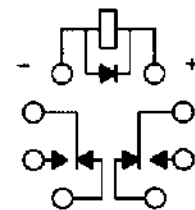

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 4/6/92 CK JERRY 11/21/97

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I. STD.
 CUST. NO. _____

TYPE HMD RELAY

HMD-26B