

COIL: @ +25°C

RESISTANCE 1620 OHMS ± 10%

NOMINAL VOLTAGE 30.0 VDC

MUST OPERATE 14.3 VDC

MUST RELEASE 1.4 VDC

ENVIRONMENT:


VIBRATION 10 CPS TO 2,500 CPS AT 20 g's

SHOCK 50 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

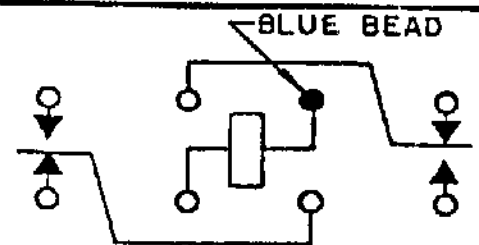

CONTACT RATING: Low Level  
2 AMPS, 28 VDC 100,000  
Operations

DR. 3/28/35

CK. OSW

**Communications Instruments, Inc.**

CUST. QPL  
 CUST. NO. M39016/44-053M

TYPE H MS RELAY

HMS1201S118M