


REV. 0  
DCO 17259

COIL: @ 25°C	
RESISTANCE	1620 OHMS ±10%
NOMINAL VOLTAGE	30.0 VDC
MUST OPERATE	14.3 VDC
MUST RELEASE	8.6 VDC MAX, 1.4 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 2500 CPS @ 20 g's
SHOCK	50 g's 11 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE 6 MS MAX
	RELEASE 5 MS MAX
	CONTACT STABILIZATION 2.5 MS MAX

CUSTOMER DATA SHEET

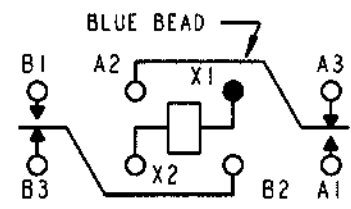

TERMINAL VIEW

CONTACT RATING:	2 AMPS 28 VDC
	0.1 AMP 115 VAC RESISTIVE 0.5 AMPS
	28 VDC INDUCTIVE 100,000 OPERATIONS

DR. ASB 9/06/01 CK. 7LG 9-6-01



CUST.	QPL
CUST. NO.	M39016/44-053P REV.

"HMS" RELAY

HMS1201S118P