


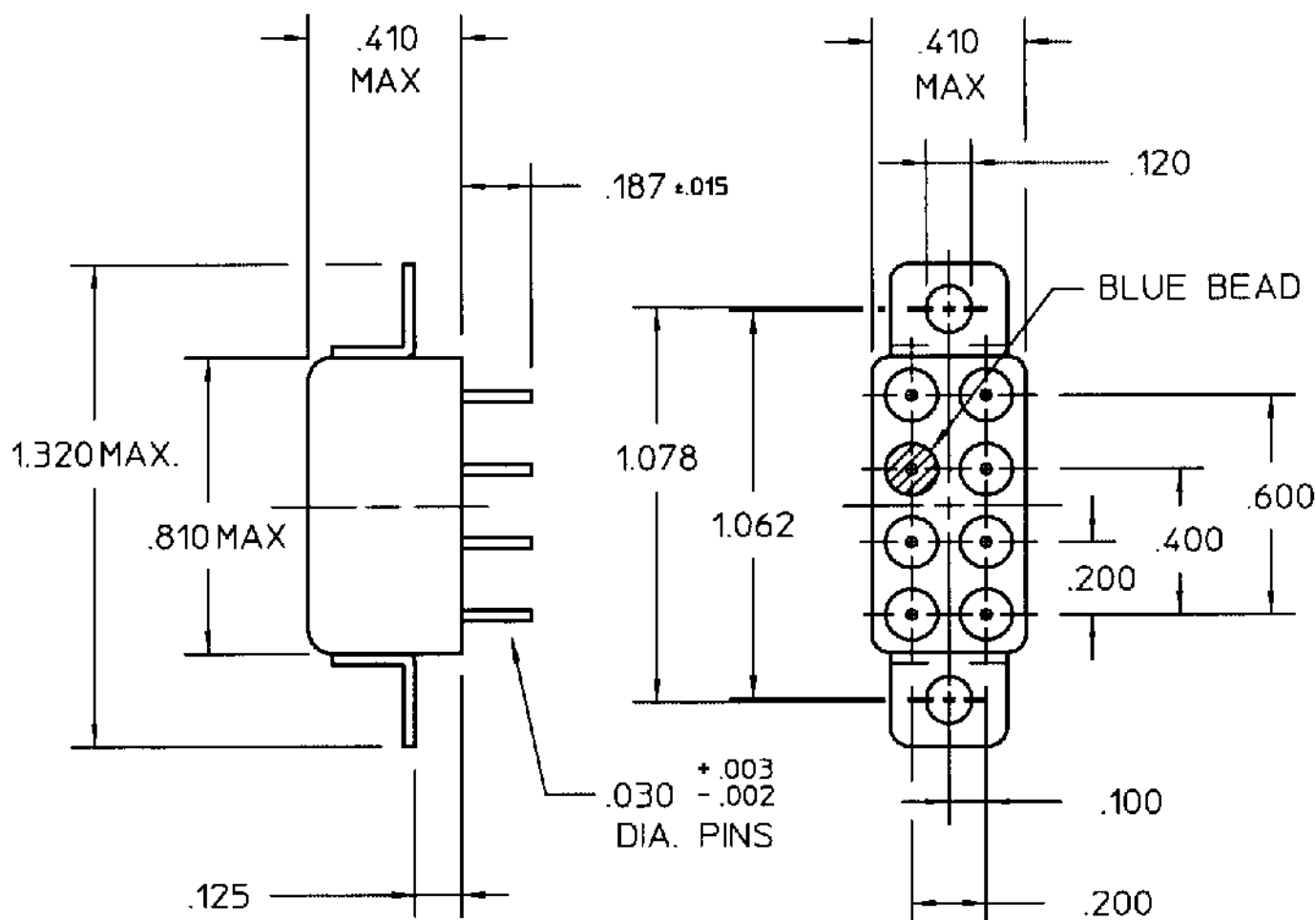

REV. 1

DCO 15768


COIL: @ 25°C
 RESISTANCE 310 OHMS ±10%
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 5.6 VDC
 MUST RELEASE 0.55 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 2500 CPS @ 20 g's
 SHOCK 50 g's 11 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 6 MS MAX.
 RELEASE 5 MS MAX.
 CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

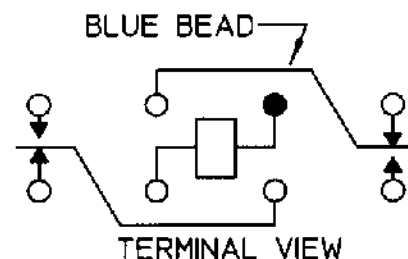

CONTACT RATING: LOW LEVEL TO 2A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 4/20/93 CK. GQH 8/9/99

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. C. I. I. STD.
 CUST. NO. REV.

"HMS" RELAY

HMS1230S003