


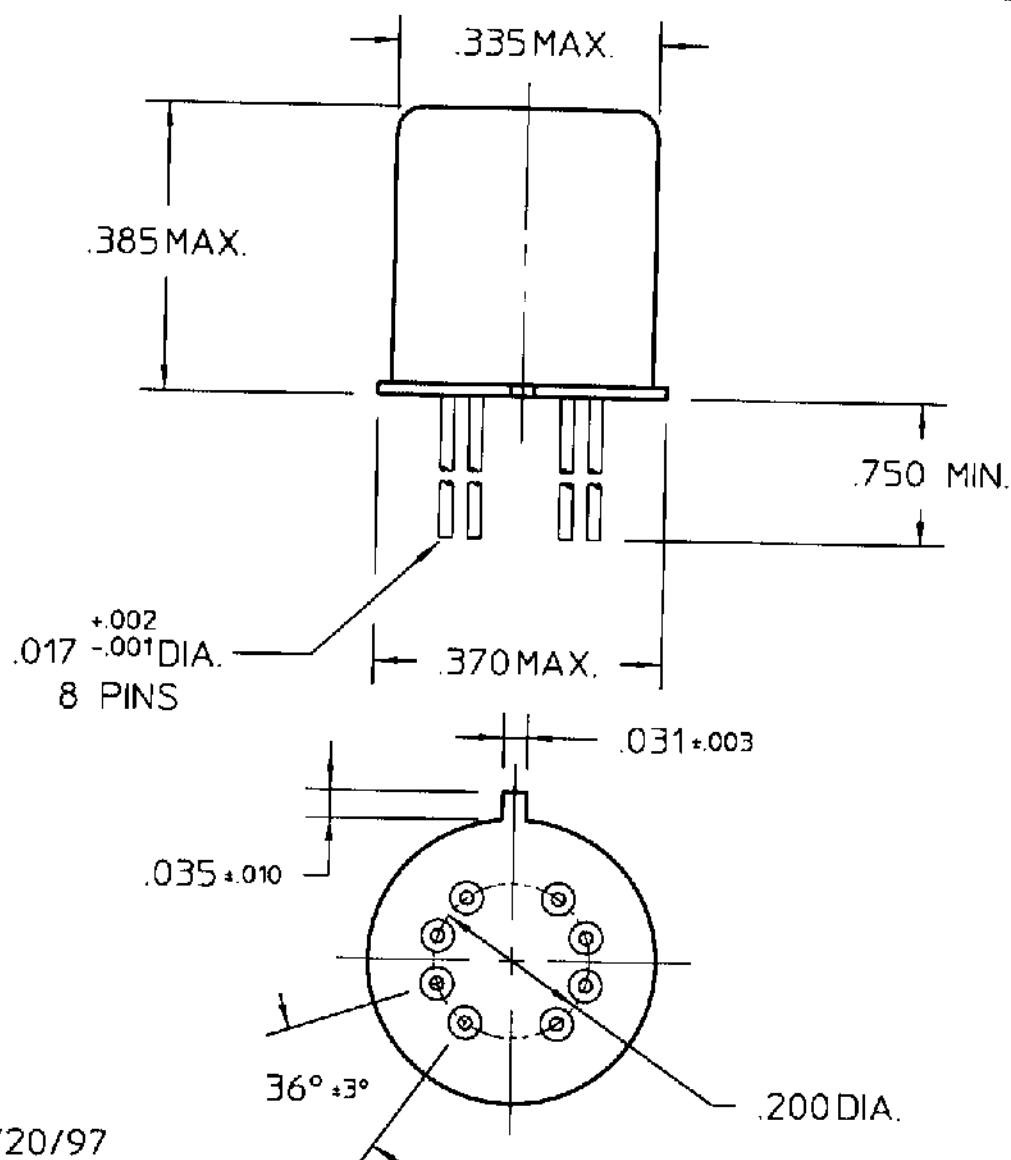

REV 3 11/20/97

COIL:

RESISTANCE 100 OHMS $\pm 10\%$

NOMINAL VOLTAGE 5.0 VDC

MUST OPERATE 3.5 VDC

MUST RELEASE

ENVIRONMENT:

VIBRATION 100 CPS TO 500 CPS @ 10 g's


SHOCK 30 g's 6 MS. DURATION

TEMPERATURE -55 $^{\circ}$ C TO +85 $^{\circ}$ C

NOTES: OPERATE TIME 6.0 MS MAX

RELEASE TIME 3.0 MS MAX

CUSTOMER DATA SHEET

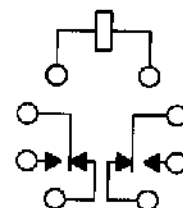

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 11/14/91 *CK* 11/20/97

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. C. I. I.

CUST. NO STD.

TYPE HS RELAY

HS-5B