

REV. 1 11/20/97

COIL:


RESISTANCE 1600 OHMS ± 10%
 NOMINAL VOLTAGE 18.0 VDC
 MUST OPERATE 13.5 VDC
 MUST RELEASE _____

ENVIRONMENT:

VIBRATION 100 CPS TO 500 CPS @ 10 g's
 SHOCK 30 g's 6 MS. DURATION
 TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 6.0 MS MAX
RELEASE TIME 7.5 MS MAX

CUSTOMER DATA SHEET

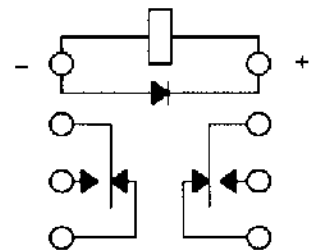

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000
OPERATIONS

DR. R.B. 12/3/92 *CK* 4/20/97

COMMUNICATIONS INSTRUMENTS, INC.

CUST. C. I. I. STD
 CUST. NO. _____

TYPE "HSD" RELAY

HSD2-18B