


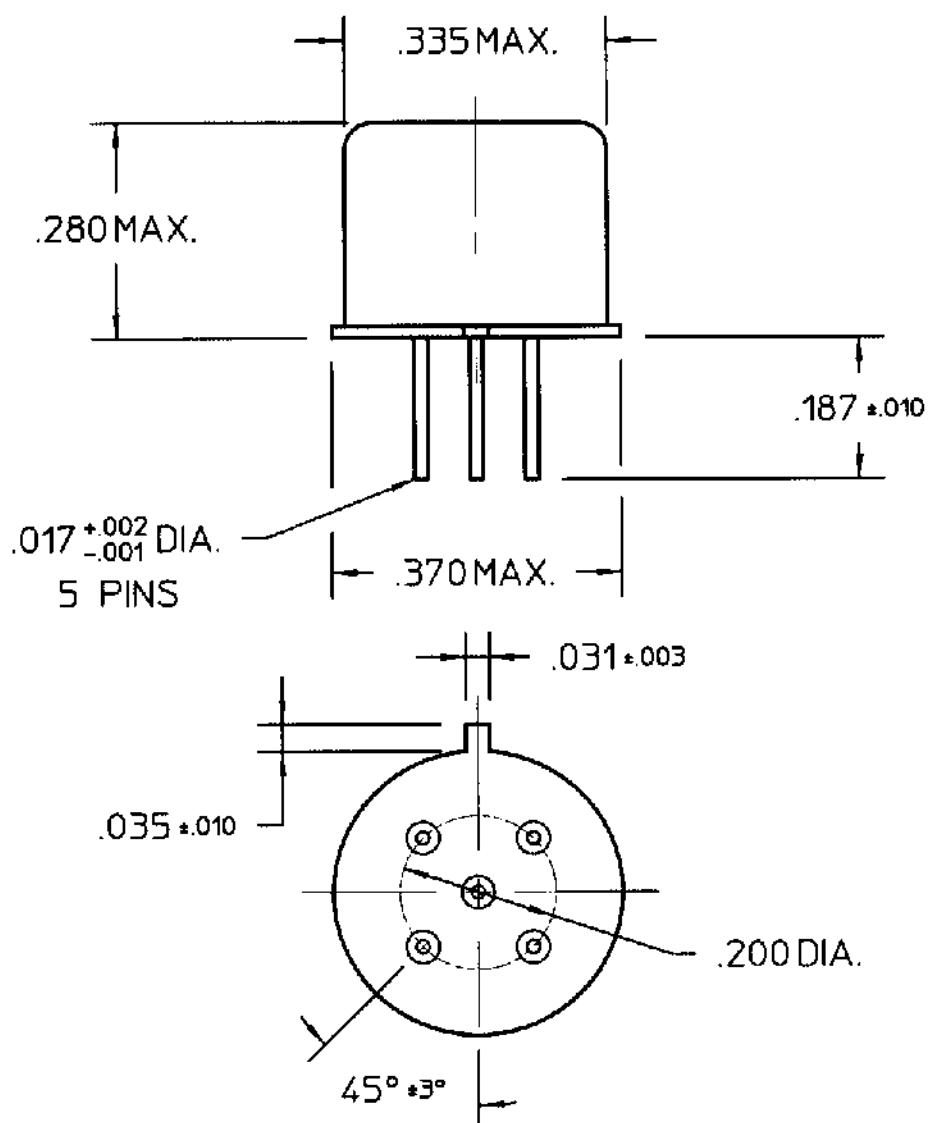

REV. 0
DCO 141756


COIL: @ 25°C
RESISTANCE 63 OHMS $\pm 10\%$
NOMINAL VOLTAGE 5.0 VDC
MUST OPERATE 2.8 VDC
MUST RELEASE 1.7 VDC MAX, 0.23 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX.
RELEASE TIME 2.0 MS MAX.
CONTACT STABILIZATION TIME 2.0 MS MAX.

CUSTOMER DATA SHEET

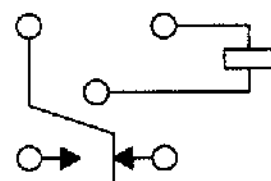

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 2/9/00

CK *[Signature]* 2/9/00



COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/7-014M REV.

'J1MA' RELAY

J1MAP-5XM