
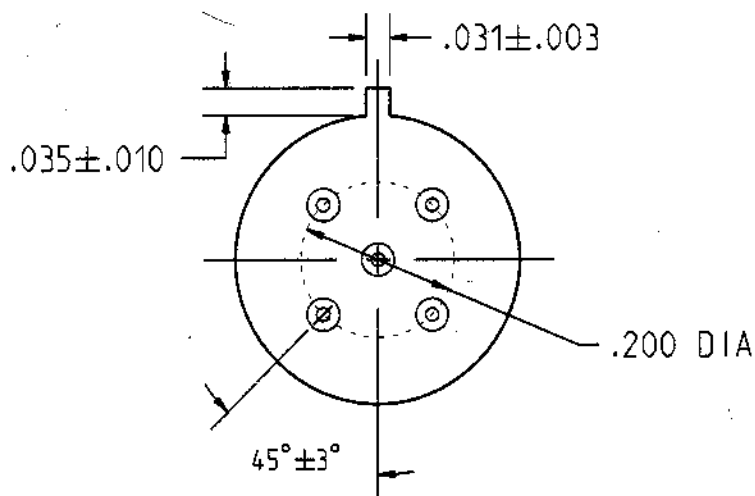


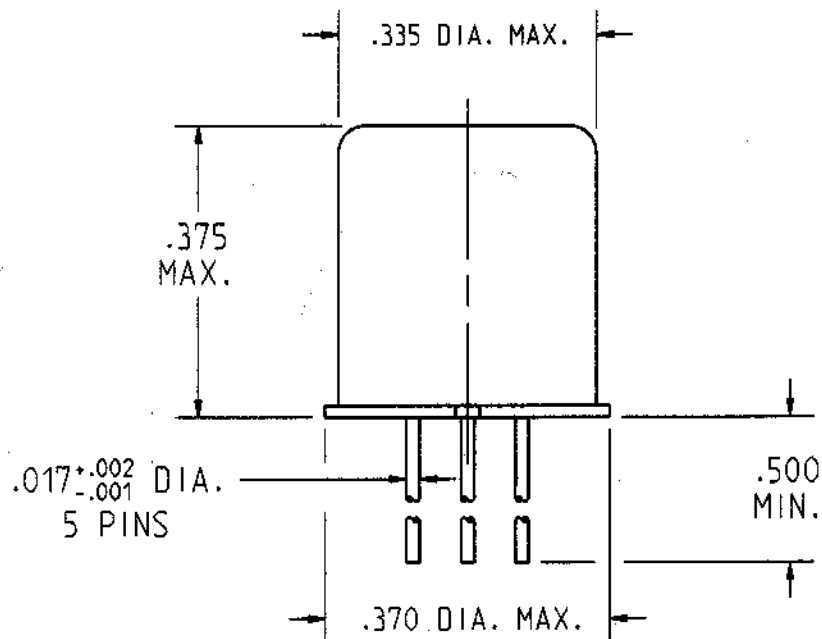


REV. 0
DCO 143835

COIL: @ 25°C
RESISTANCE 4000 OHMS ±10%
NOMINAL VOLTAGE 26.5 VDC
MUST OPERATE 15.4 VDC
MUST RELEASE 8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:
VIBRATION 10 Hz TO 3000 Hz @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX.
RELEASE TIME 7.5 MS MAX.
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

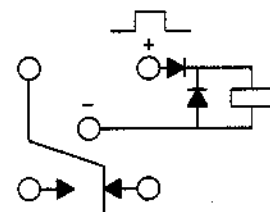

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. ASB 18NOV03

CR. [Signature] 11/18/03

CII Technologies
advanced control electronic solutions

CUST. QPL
CUST. NO. M39016/26-036L REV.

"J1MSDD" RELAY

J1MSCDD-26XL