


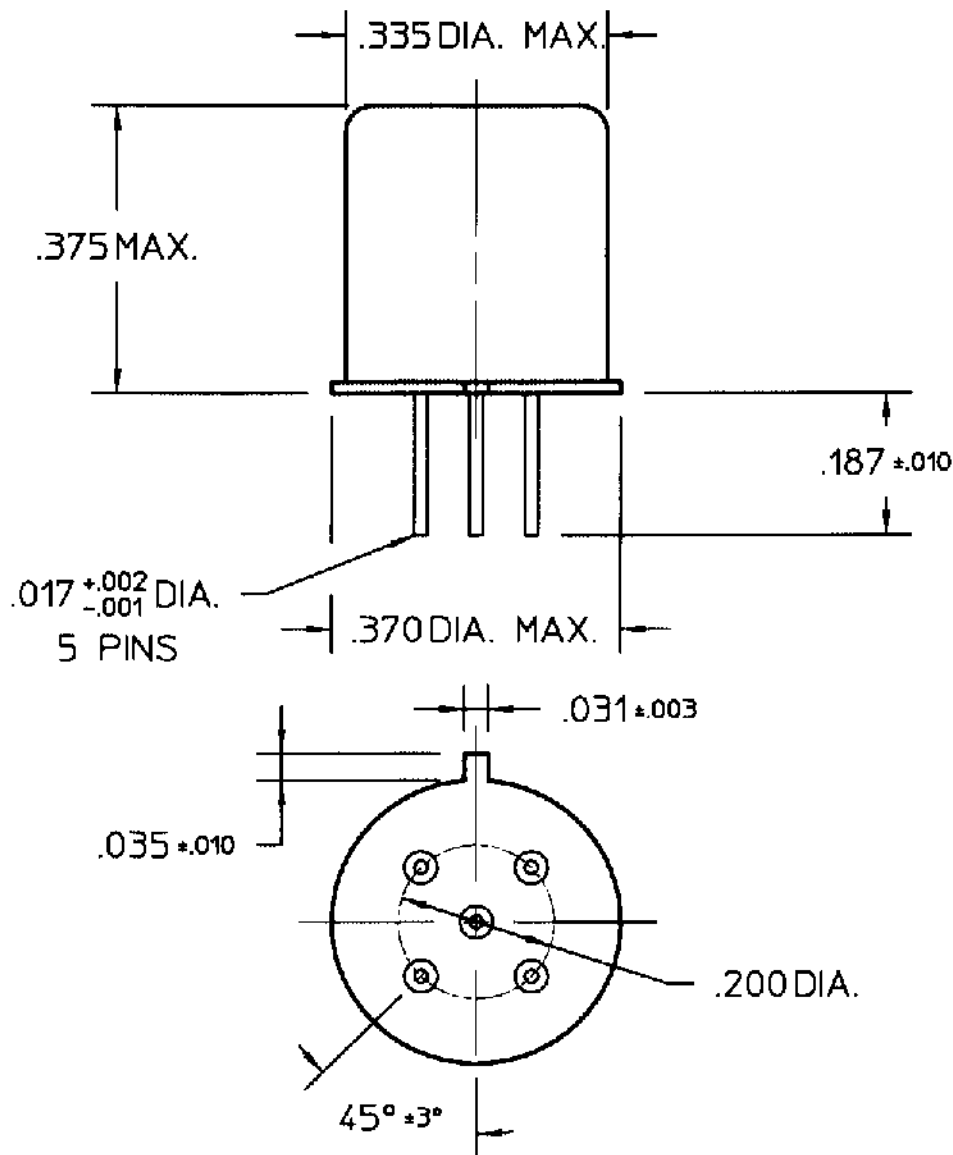

REV. 0
DCO 140859

COIL: @ 25°C
RESISTANCE 4000 OHMS $\pm$ 10%
NOMINAL VOLTAGE 26.5 VDC
MUST OPERATE 14.2 VDC
MUST RELEASE 8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:


VIBRATION 10 CPS TO 3000 CPS @ 30 g's

SHOCK 75 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX.
RELEASE TIME 7.5 MS MAX.
CONTACT STABILIZATION TIME 2.0 MS MAX.

CUSTOMER DATA SHEET

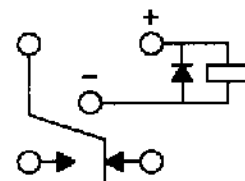

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 1/20/99 CK. JERRY 1/20/99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/25-028M

TYPE J1MSD RELAY

J1MSPD-26XM