


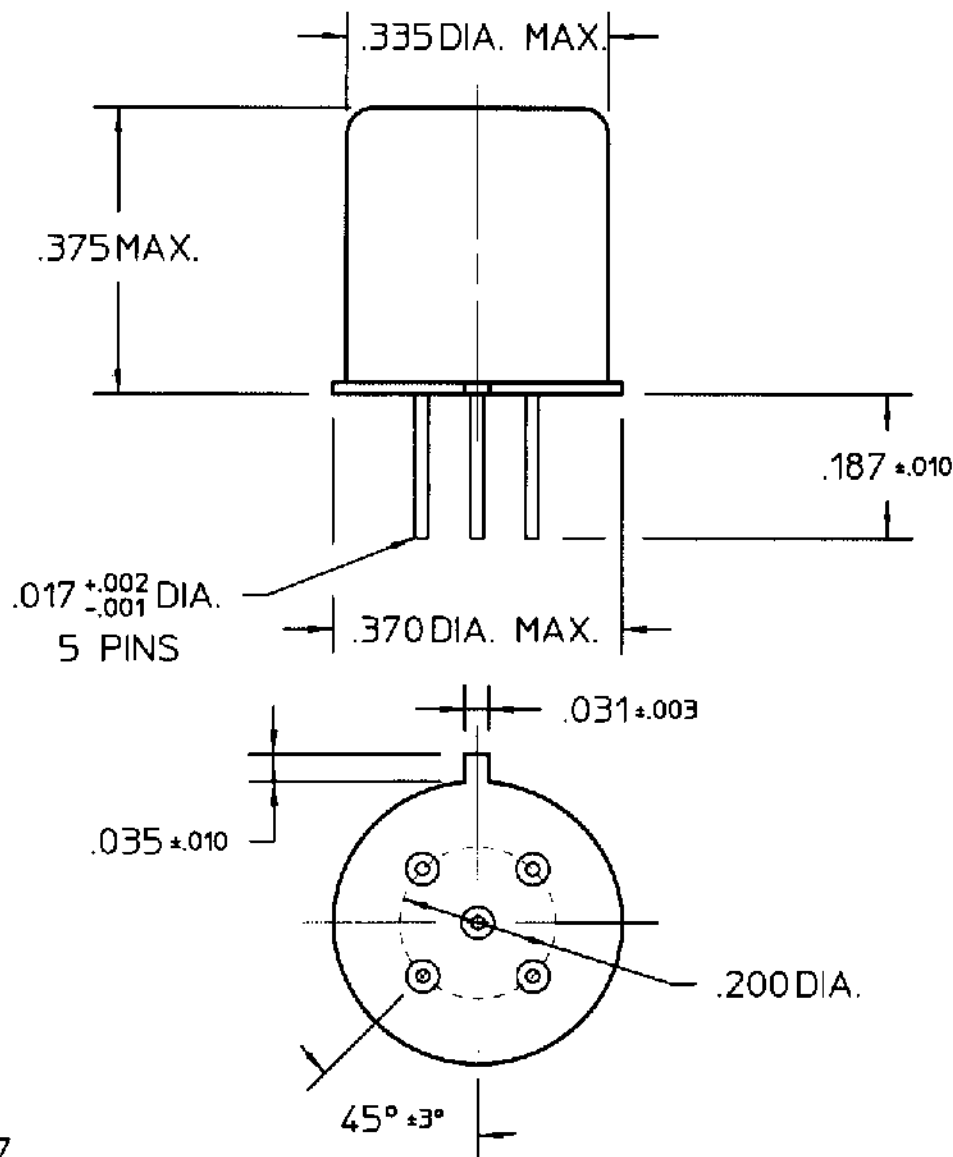

REV. 0

DCO 141597

COIL: @ 25°C
 RESISTANCE 11,000 OHMS ±10%
 NOMINAL VOLTAGE 40.0 VDC
 MUST OPERATE 23.3 VDC
 MUST RELEASE 13.3 VDC MAX, 2.0 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's

SHOCK 75 g's 6 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX.

RELEASE TIME 7.5 MS MAX.

CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

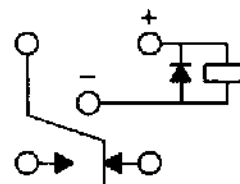

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 12/9/99

CK. JERRY C 12/9/99

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. QPL
 CUST. NO. M39016/25-030L REV.

J1MSD RELAY

J1MSPD-40XL