

REV. 0
DCO 143832


COIL: @ 25°C	
RESISTANCE	880 OHMS ±10%
NOMINAL VOLTAGE	18.0 VDC
MUST OPERATE	10.6 VDC
MUST RELEASE	6.0 VDC MAX, 0.91 VDC MIN.

ENVIRONMENT:

VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX
RELEASE TIME 4.0 MS MAX
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

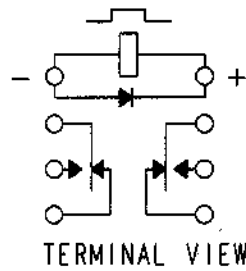

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000 OPERATIONS

DR. ASB 14NOV03

ERRA 11/13/03



CUST. QPL
CUST. NO. M39016/15-104L REV. _____

"JMADC" RELAY

JMADC-18XLS