

REV. 0
DCO 143839


| | |
|-----------------|---------------------------|
| COIL: @ 25°C | |
| RESISTANCE | 880 OHMS ±10% |
| NOMINAL VOLTAGE | 18.0 VDC |
| MUST OPERATE | 11.5 VDC |
| MUST RELEASE | 7.3 VDC MAX, 1.4 VDC MIN. |

ENVIRONMENT:

| | |
|-------------|---------------------------|
| VIBRATION | 10 Hz TO 3000 Hz @ 30 g's |
| SHOCK | 75 g's 6 MS. DURATION |
| TEMPERATURE | -65 °C TO +125 °C |

NOTES: OPERATE TIME 2.0 MS MAX
RELEASE TIME 4.0 MS MAX
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

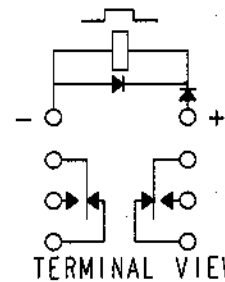

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 10DEC03

[Signature] 12/11/03

CII Technologies
advanced control electronic solutions

CUST. GPL
CUST. NO. M39016/20-065L REV. _____

"JMADD" RELAY

JMACDD-18XLS