


REV. 0  
DCO 142077

COIL: @ 25°C	
RESISTANCE	390 OHMS $\pm$ 10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	7.0 VDC
MUST RELEASE	4.0 VDC MAX, 0.63 VDC MIN

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX.  
RELEASE TIME 4.0 MS MAX.  
CONTACT STABILIZATION 2.0 MS MAX.

CUSTOMER DATA SHEET

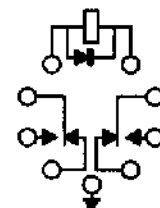

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 6/6/00

*Gray* 6/6/00

COMMUNICATIONS  
INSTRUMENTS, INC.

CUST. QPL  
CUST. NO. M39016/15-091M REV.

"JMAD" RELAY

JMACDG-12XM