

REV. 0

DCO 141856


GROUND PIN

COIL: @ 25°C	
RESISTANCE	880 OHMS ±10%
NOMINAL VOLTAGE	18.0 VDC
MUST OPERATE	10.5 VDC
MUST RELEASE	6.0 VDC MAX, 0.91 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE TIME 2 MS MAX
	RELEASE TIME 4 MS MAX
	CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

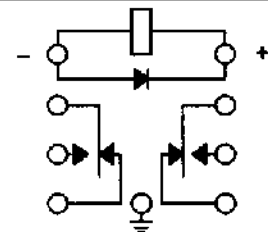

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000
OPERATIONS

DR. B.D. 3/14/00

CK VERRA 3/14/00



CUST. QPL
 CUST. NO. M39016/15-116L REV. _____

'JMAGD' RELAY

JMACDG-18XLS