


REV. 0
DCO 141325

COIL: @ 25°C	
RESISTANCE	220 OHMS \pm 10%
NOMINAL VOLTAGE	9.0 VDC
MUST OPERATE	5.3 VDC
MUST RELEASE	3.0 VDC MAX, 0.54 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE TIME 2 MS MAX
	RELEASE TIME 4 MS MAX
	CONTACT STABILIZATION 2.5 MS MAX

CUSTOMER DATA SHEET

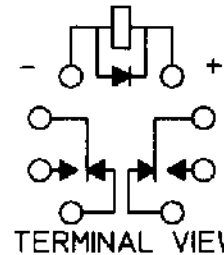

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 8/31/99 (CK) *ERRY* 9/1/99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/15-036M REV.

JMAD RELAY

JMAPD-9XM