


REV. 1  
DCO 143744

COIL: @ 25°C	
RESISTANCE	1560 OHMS ± 10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	14.2 VDC
TURN-ON BASE CURRENT	0.13 mA DC
MUST RELEASE	8.0 VDC MAX., 1.37 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	TURN-ON TIME 2.0 MS MAX.
	TURN-OFF TIME 7.5 MS MAX.
	CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

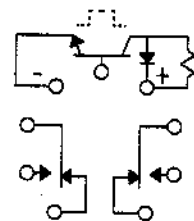

TERMINAL VIEW

CONTACT RATING:	LOW LEVEL TO 1A
	28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 15APR03

*Handwritten signature and date: 4/21/03*

**CII Technologies**  
advanced control electronic solutions

CUST. GPL	
CUST. NO. M28776/1-024L	REV. _____

"JMPT" RELAY

JMPT-26XL