


REV. 1 9/12/97

COIL: @ 25°C	
RESISTANCE	390 OHMS ± 10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	7.0 VDC
MUST RELEASE	4.0 VDC MAX, 0.63 VDC MIN.

CUSTOMER DATA SHEET

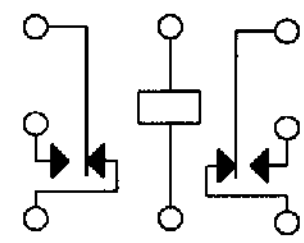

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS

NOTES:	OPERATE TIME 2.0 MS MAX
	RELEASE TIME 15 MS MAX
	CONTACT STABILIZATION 2.5 MS MAX

DR. R.B. 5/9/97 CK *EPM* 9/12/97



CUST. QPL
CUST. NO. M39016/17-040P

TYPE JMGA RELAY

JMGAC-12PW