

REV. 1 9/12/97

COIL: @ 25°C	
RESISTANCE	880 OHMS ± 10%
NOMINAL VOLTAGE	18.0 VDC
MUST OPERATE	10.5 VDC
MUST RELEASE	6.0 VDC MAX, 0.91 VDC MIN.


ENVIRONMENT:

VIBRATION	10	CPS TO	3000	CPS @	30	g's
SHOCK	75	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES:

OPERATE TIME	2.0 MS MAX
RELEASE TIME	1.5 MS MAX
CONTACT BOUNCE	15 MS MAX

CUSTOMER DATA SHEET

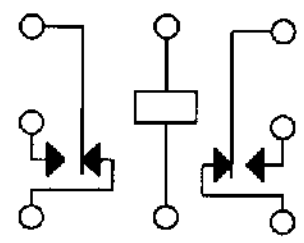

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 5/9/97 *[Signature]* 9/12/97



CUST. QPL
CUST. NO. M39016/17-035L

TYPE JMGA RELAY

JMGAC-18L