


REV. 0
DCO 141598

COIL: @ 25°C
 RESISTANCE 200 OHMS ± 10%
 NOMINAL VOLTAGE 6.0 VDC
 MUST OPERATE 3.4 VDC
2.0 VDC MAX, 0.28 VDC MIN.
 MUST RELEASE _____

ENVIRONMENT: 10 3000 30
 VIBRATION 75 CPS TO 6 CPS @ _____ g's
 SHOCK _____ g's _____ MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 7.5 MS MAX
CONTACT STABILIZATION 2.5 MS MAX.

CUSTOMER DATA SHEET

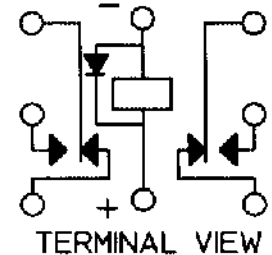

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. B.D. 5/10/99 *CK* 12/19/99



CUST. QPL
 CUST. NO. M39016/42-034M REV. _____ JMGSD RELAY

JMGSCD-6M