


REV. 0
DCO 141468

COIL: @ 25°C	
RESISTANCE	100 OHMS ±10%
NOMINAL VOLTAGE	5.0 VDC
MUST OPERATE	2.6 VDC
MUST RELEASE	1.4 VDC MAX, 0.23 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE TIME 4.0 MS MAX
	RELEASE TIME 2.0 MS MAX
	CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

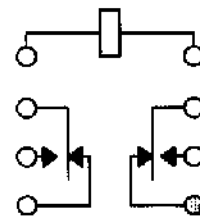

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000
OPERATIONS

DR. B.D. 11/9/99 *CK. Free* 11/9/99



CUST. QPL
CUST. NO. M39016/11-041L REV. _____

JMS RELAY

JMSC-5XLS