


REV. 0
DCO 143373

COIL: @ 25°C	
RESISTANCE	3300 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	15.2 VDC
MUST RELEASE	10.8 VDC MAX; 1.7 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE TIME 4.0 MS MAX. RELEASE TIME 7.5 MS MAX. CONTACT STABILIZATION TIME 2.0 MS MAX.

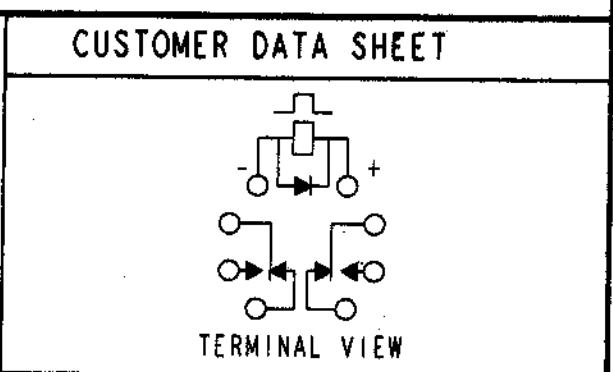

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. ASB 12/19/01 *CK* 12/19/01



CUST. GPL
CUST. NO. M39016/21-038P REV. _____ "JMSDD" RELAY

JMSCDD-26XP