


REV. 0

DCO 143180

COIL: @ 25°C	
RESISTANCE	850 OHMS ±10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	7.0 VDC
MUST RELEASE	4.0 VDC MAX, 0.64 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE TIME 4.0 MS MAX.
	RELEASE TIME 7.5 MS MAX.
	CONTACT STABILIZATION 2.0 MS MAX.

CUSTOMER DATA SHEET

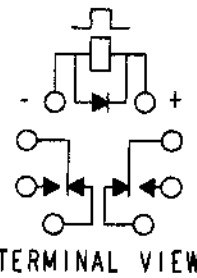

CONTACT RATING: LOW LEVEL TO IA
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 8/29/01 *CA Jerez 8/30/01*

CII Technologies
 advanced control electronic solutions

CUST. OPL
 CUST. NO. M39016/16-027P REV. _____

"JMSD" RELAY

JMSPD-12XP