


REV. 0
DCO 140947

COIL: @ 25°C	
RESISTANCE	6500 OHMS ± 10%
NOMINAL VOLTAGE	36.0 VDC
MUST OPERATE	20.0 VDC
MUST RELEASE	10.0 VDC MAX, 1.8 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE TIME 4 MS MAX
	RELEASE TIME 7.5 MS MAX
	CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

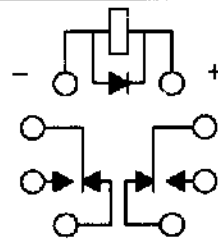

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 3/8/99 CK. EBBY 3-8-99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/16-021L

TYPE JMSD RELAY

JMSWD-36XI