

REV. 0  
DCO 142074


COIL: @ 25°C	
RESISTANCE	100 OHMS ± 10%
NOMINAL VOLTAGE	5.0 VDC
MUST OPERATE	2.6 VDC
MUST RELEASE	1.4 VDC MAX, 0.23 VDC MIN.

ENVIRONMENT:

VIBRATION	10	CPS TO	3000	CPS @	30	g's
SHOCK	75	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES: OPERATE TIME 4.0 MS MAX  
RELEASE TIME 7.5 MS MAX  
CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

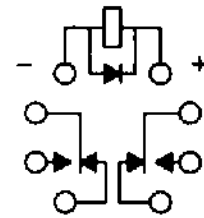

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 6/6/00

*Handwritten signature: K. Lerry 6/6/00*

**COMMUNICATIONS INSTRUMENTS, INC.**

CUST. QPL  
CUST. NO. M39016/16-017L REV. \_\_\_\_\_

\*JMSD\* RELAY

**JMSWD-5XL**