


REV. 0
DCO 142073

COIL: @ 25°C	
RESISTANCE	64 OHMS ±10%
NOMINAL VOLTAGE	5.0 VDC
MUST OPERATE	2.9 VDC
MUST RELEASE	2.2 VDC MAX, 0.8 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE TIME 4.0 MS MAX
	RELEASE TIME 7.5 MS MAX
	CONTACT STABILIZATION 2.0 MS MAX

CUSTOMER DATA SHEET

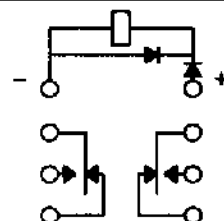

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 6/6/00 *CK [Signature]* 6/6/00



CUST. QPL
CUST. NO. M39016/21-007P REV. _____

JMSDD RELAY

JMSWDD-5XP