


COIL: 26.5 VDC NOMINAL

CUSTOMER DATA SHEET

WINDING #1	WINDING #2
1000 OHMS $\pm 10\%$	1000 OHMS $\pm 10\%$
8-13 VDC MUST OPERATE	8-13 VDC MUST OPERATE

CONTACTS WILL SWITCH FROM THE INDICATED POSITION WHEN EITHER COIL IS ENERGIZED WITH POLARITY SHOWN.

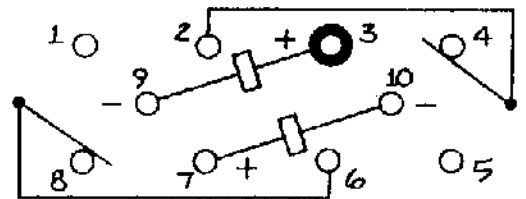

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 50 g's 11 MS.DURATION
 TEMPERATURE -65 °C TO +125 °C

CONTACT RATING: 2 AMP / 28 VDC RESISTIVE

NOTES: _____

DR. R.B. 4-5-90 | CK. JAW 4-5-90



CUST. CII STD
 CUST. NO. _____

TYPE "LS" RELAY

LSAW-ZC-24B