


REV. 0

DCO 62811

COIL: @ 25°C	
SET	RESET
63 OHMS ±10% @ 25°C	63 OHMS ±10% @ 25°C
3.25 VDC NOMINAL VOLTAGE	3.25 VDC NOMINAL VOLTAGE
6.0 VDC MUST OPERATE	6.0 VDC MUST OPERATE
ENVIRONMENT:	
VIBRATION <u>10</u> Hz	<u>2000</u> Hz <u>20</u> g's
SHOCK <u>100</u> g's	<u>6</u> MS. DURATION
TEMPERATURE <u>-65</u> °C TO	<u>+125</u> °C
NOTES: <u>SET &amp; RESET TIME 5 MS MAX.</u>	
<u>BOUNCE 2 MS MAX.</u>	
CUST. <u>C. I. I. STD.</u>	TYPE 'LS' RELAY
CUST. NO. _____	

CUSTOMER DATA SHEET

CONTACTS WILL SWITCH WHEN EITHER COIL IS ENERGIZED WITH POLARITY SHOWN

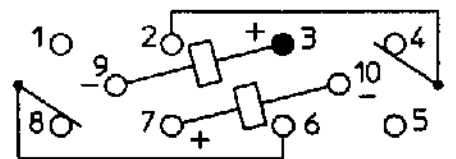

TERMINAL VIEW

CONTACT RATING: 2 AMPS 28 VDC  
RESISTIVE 100,000 OPERATIONS

DR. B.D. 7/1/99 CK. *[Signature]*



LSAW-2C-6B